




81532102-rotatable/81 532 102



2-hand control relay


Pressure delay sensor	✓ 1
Pressure switches	✓ 1
Adjustable pressure switches (manostats) and Adjustable vacuum switches (vacuostats)	✓ 1
Leak sensor and amplifier relays	✓ 1
Logic elements and Timers (with adjustable timing)	✓ 1
Regulator accessories	✓ 1
Memory element	
Miniature power valve	✓ 1
Push-in connection for semi-rigid tubing Ø 4 (NFE 49100) mm	rotatable
Mounting	DIN rail 35 mm EN 50022
Weight (g)	52

Dimension Diagram : 81 532 104 - 81 532 102

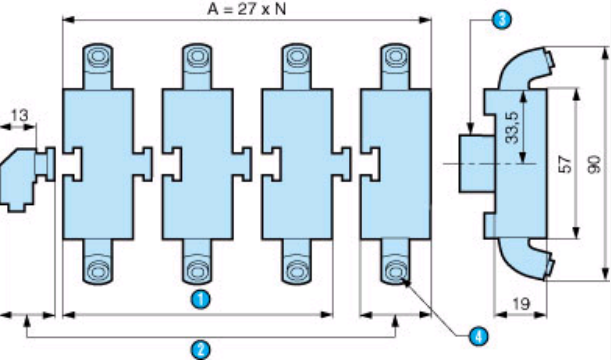

N°	Legend
1	Associable sub-bases
2	Sub-base supplied with inlet connection
3	Mounted on Ω rail EN 50022
4	Push-in connection for semi-rigid tubing Ø 4 mm (NFE 49100)

 : Bases for elements and relays - Front connecting 81 532 102/104



N°	Legend
1	Input port (green - port 1)
2	Output port (red - port 3)
3	Input port integral to sub-base
4	Input indicator (green)
5	Output indicator (red)
6	1/4 turn screws
7	Marking tag
8	Arrow indicating flow direction
9	Mounting tongue
10	Mounting groove

