


BN 8 - DIN 912 - ISO 4762

Hexagon socket head cap screws
partially threaded
partially threaded

DIN 912
ISO 4762

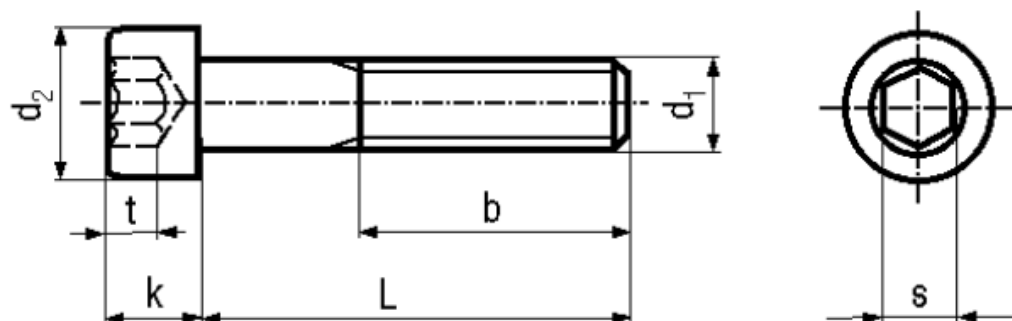

Material	Steel	Tensile strength	1200 N/mm2
Surface	black	Proof stress 0,2%	1080 N/mm2
Quality	12.9	Elongation after fracture	min. 8%

Article No. - 1009257

d ₁	M12
L	200
d ₂	18
b	36
k	12
s	10
t min.	6

DIN 912: Standard withdrawn

M18; M22; M27: Not included in ISO 4762.