


BN 806

Disc springs
works standard

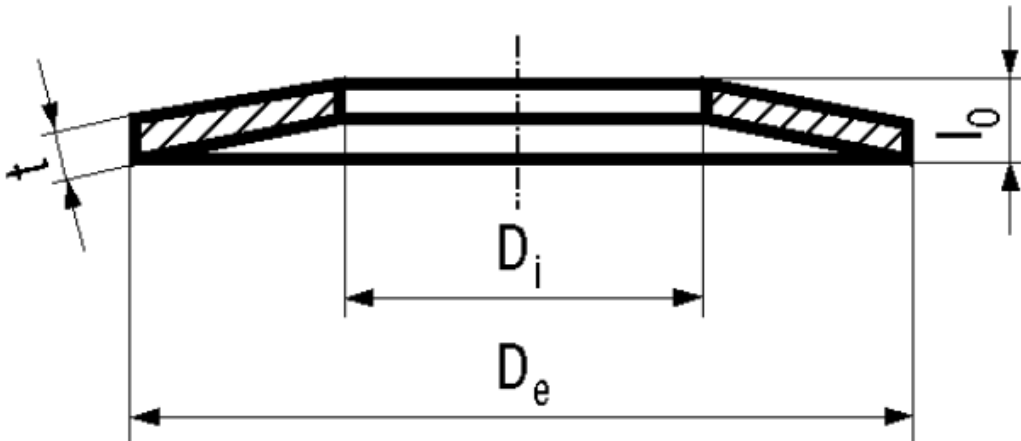

Material	Spring steel	Hardness	42-52 HRC
Surface	phosphated and lubricated		

Article No. - 1282425	
De	15
Di	5,2
t (t')	0,5
lo	1
0,5 h ₀	221 N
0.75 h ₀	278 N
0,9 h ₀	305 N

$h_0=l_0-t$
Disc springs thickness more than 6mm, with bearing surface and reduced thickness (t').