


BN 351

Slotted pan head screws

DIN 85 A
~ISO 1580
~UNI 6108

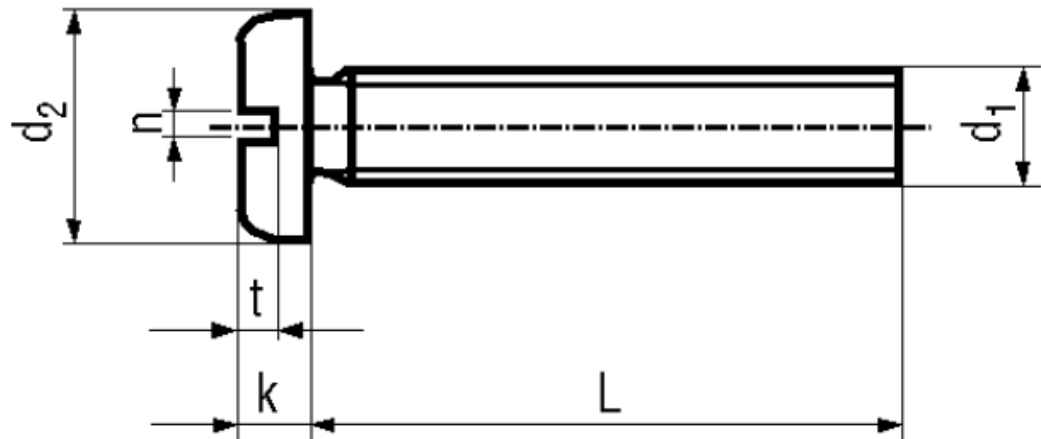

Material	Steel	Tensile strength	800 N/mm2
Surface	zinc plated blue	Proof stress 0,2%	640 N/mm2
Quality	8.8	Elongation after fracture	min. 12%

Article No. - 1134396	
d_1	M3
L	8
d_2	6
k max.	1,8
n	0,8
t min.	0,7
Proof load (N)	2920

DIN 85 A: Standard withdrawn
M2,5 to ISO 1580
All lengths fully threaded.