


BN 941 - DIN 7971 C - ~ISO 1481

Slotted pan head tapping screws
with cone end type C
case-hardened

DIN 7971 C
~ISO 1481
~UNI 6951AB

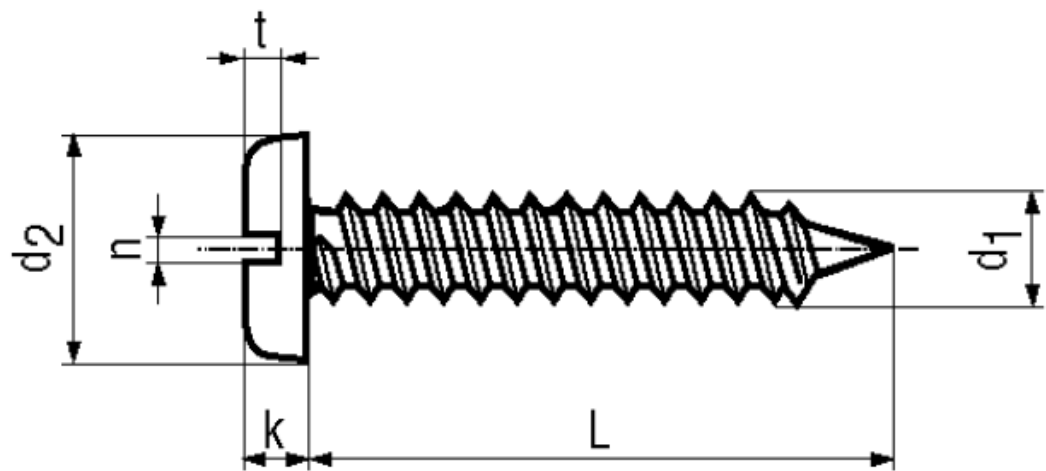

Material	Steel	Hardness	450 HV
Surface	zinc plated		

Article No. - 1372564	
d ₁	ST 4,2
L	9,5
d ₂ max.	8,2
k max.	2,45
n	1,2
t min.	1,15

DIN 7971: Standard withdrawn

DIN 7971 type F blunt-point see BN 992.

Fasteners steel case-hardened ≥ 320 HV with electroplated coatings: Susceptible to hydrogen embrittlement!