


BN 3332

Self clinching captive studs
heat-treated

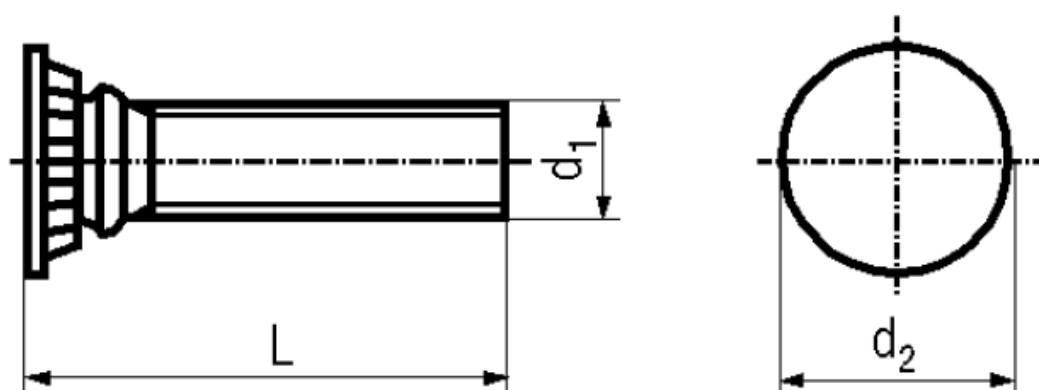

Material	Steel	Hardness	300-380 HV
Surface	zinc plated blue		

Article No. - 1536729	
d ₁	M6
L	12
d ₂	8
Min. sheet metal thickness	1,5
Drill-ø	6,1
Distance to edge	8