


Crimping contact
HDC-C-HE-BM0.75-1.00AG

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-2083
www.weidmueller.com

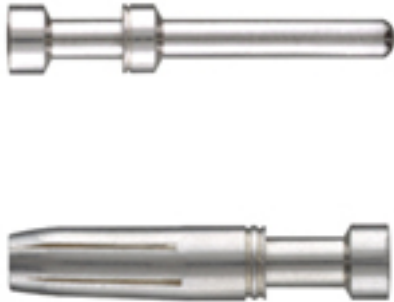

Crimps provide a electrical and mechanical connection between wire and contact that is both secure and reliable. The optimal crimp connection is gas-tight and corrosion-resistant.

General ordering data

Order No.	1201200000
Type	HDC-C-HE-BM0.75-1.00AG
Version	Heavy Duty Connectors, Contact, HE, HEE, HQ, MixMate, CM HE, CM BUS (CSB), Female, Conductor cross-section, max.: 1, turned, Copper alloy
GTIN (EAN)	4008190044480
Qty.	100 pc(s).

Crimping contact HDC-C-HE-BM0.75-1.00AG

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-2083
 www.weidmueller.com

Technical data

Dimensions

Net weight	1.45 g	Diameter	4.5 mm
------------	--------	----------	--------

General data

Contact diameter, male Ø	2.5 mm	Production methods	turned
Stripping length, rated connection	7.5 mm	Type	Female
Type of connection	Crimp connection	Material	Copper alloy
Surface finish	silver	Volume resistance	≤ 2mΩ

Classifications


ETIM 2.0	EC000796	ETIM 3.0	EC000796
UNSPSC	30-21-18-01	eClass 4.1	27-14-08-05
eClass 5.1	27-14-34-19	eClass 6.0	27-26-12-02
eClass 7.0	27-44-02-04		

Product information


Descriptive text accessories	For further accessories, see chapter J - tools, see chapter K
------------------------------	---

Crimping contact
HDC-C-HE-BM0.75-1.00AG

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-2083
www.weidmueller.com

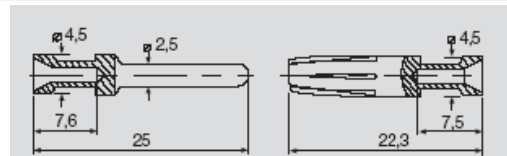Drawings


Leiterquerschnitt	Abisolierlänge	
0,50 mm ²	AWG 20	7,5 mm
0,75 - 1,00 mm ²	AWG 18	7,5 mm
1,50 mm ²	AWG 16	7,5 mm
2,50 mm ²	AWG 14	7,5 mm
4,00 mm ²	AWG 12	7,5 mm

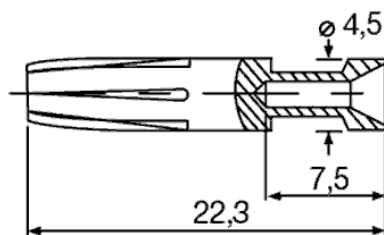

Crimping contact
HDC-C-HE-BM0.75-1.00AG

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-2083
 www.weidmueller.com

Accessories
Non-contact tools


Tools for dismantling Weidmüller crimp contacts

General ordering data

Order No.	Type	Version	GTIN (EAN)	Qty.
1866750000	Removal Tool HE	Heavy Duty Connectors, Tools, Contact removal tool	4032248437078	1 pc(s).

... for milled contacts

Crimping tools for turned contacts

- Ratchet guarantees precise crimping
- Release option in the event of incorrect operation
- With stop for exact positioning of the contacts.

General ordering data

Order No.	Type	Version	GTIN (EAN)	Qty.
9205430000	CTIN CM 1.6/2.5	Crimping tool for contacts, Turned contacts, Crimping range, min.: 0.14, 4-indent crimp	4032248733446	1 pc(s).

**Crimping contact
HDC-C-HE-BM0.75-1.00AG**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-2083
www.weidmueller.com

Accessories**Crimping tools**

Weidmüller offers a variety of crimping tools, no-contact tools, and fibre optic tools.

General ordering data

Order No.	Type	Version	GTIN (EAN)	Qty.
9018490000	CTX CM 1.6/2.5	Crimping tool for contacts, Turned contacts, Crimping range, min.: 0.14, W crimp	4008190884598	1 pc(s).