



PCA.00.250.CTLC29Z

MECHANICAL DETAILS

Shell Style Model PCA* : Free receptacle with cable collet


Keying Circular (can rotate)

Housing Material Brass (chrome plated) shell and collet nut, nickel plated brass latch sleeve and mid pieces

Cable Fixing 2.8 - 3.1 mm

Variant 2 Z : Nut for fitting a bend relief

	A	L
Mm.	6.5	25
In.	0.26	0.98

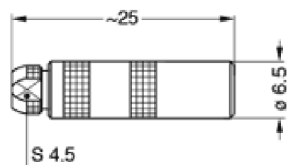

PERFORMANCE DETAIL

Insert 0.25 : 1 Coax (50 Ohm)

Insulator T: PTFE

Specifications

Contact Type: Coaxial 50 Ohm (Solder)


Max. Matings: 5000

Contact Dia.: 0.7 mm (0.028in)

Bucket Dia.: 0.6 mm (0.024in)

R (max): 6.1 mOhm

Cable type: |A|RG

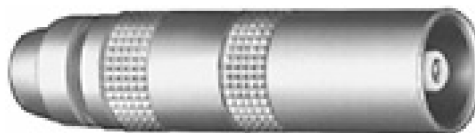


OTHER CHARACTERISTICS

Endurance (Shell) Endurance (Shell):

F ret (min): 100 N

IP Rating 50

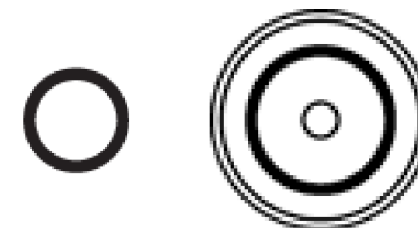

Available Download

00and01Coaxial_en.pdf

Related links

- [Contact](#)
- [Quote Request](#)
- [Catalogs Downloads](#)
- [Catalogs Requests](#)
- [Sample Request](#)
- [3D drawings](#)